




- Cost Effective MT marking system for quick and accurate identification
- Push-On Tags fit all Altech DIN Rail mount terminal blocks
- Inserted individually or as strips of 10
- Quick and easy marking
- Blank Marking Tags for customer marking
- Order with horizontal/ vertical imprint
- Standard imprints with consecutive or identical numbers/ characters
- Custom imprint with short lead time
- Supplied in packs of 100 tags/ 10 strips

BLANK MARKING TAGS

Cat No./ Type	Standard Packs			Dimensions	
	Pack	Strips	Tags	H	W
MT2	1	10	100	4.9mm	5.8mm
MT3	1	20	100	5.0mm	10.0mm
MT4	1	10	100	5.0mm	4.8mm
MT5	1	10	100	9.5mm	4.5mm
MT6	1	10	100	9.5mm	5.6mm
MT8	1	10	100	10.5mm	7.5mm
MT9	1	10	100	10.3mm	8.7mm
MT10	1	20	100	10.4mm	9.5mm
MT12	1	20	100	10.4mm	11.4mm
MT16	1	20	100	10.5mm	15.4mm
MT2G	1	10	100	5.0mm	5.0mm
MT2B4	1	10	100	5.8mm	9.1mm
Continuous Tags					
MT6F	1	10	10	9.5mm	60.0mm
MT9F	1	10	10	10.3mm	90.0mm

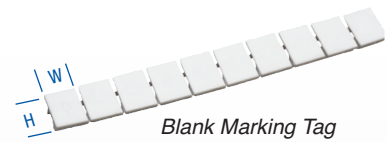

Blank Marking Tag




Horizontal Imprint



Vertical Imprint

HOW TO ORDER IMPRINTED MARKING TAGS

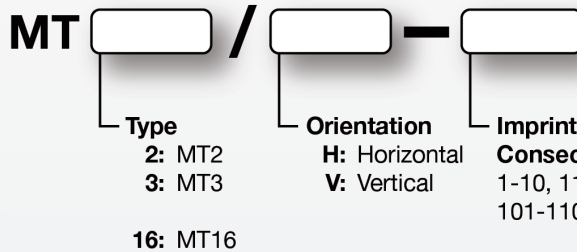

IMPRINT EXAMPLES FOR MT6

HORIZONTAL

Imprint	Cat. No.	Imprint	Cat. No.
1	MT6/H-1	131-140	MT6/H-131-140
2	MT6/H-2	141-150	MT6/H-141-150
3	MT6/H-3	151-160	MT6/H-151-160
4	MT6/H-4	161-170	MT6/H-161-170
5	MT6/H-5	171-180	MT6/H-171-180
6	MT6/H-6	181-190	MT6/H-181-190
7	MT6/H-7	191-200	MT6/H-191-200
8	MT6/H-8	1-100	MT6/H-1-100
9	MT6/H-9	1-50	MT6/H-1-50
10	MT6/H-10	A	MT6/H-A
1-10	MT6/H-1-10	B	MT6/H-B
11-20	MT6/H-11-20	C	MT6/H-C
21-30	MT6/H-21-30	L1	MT6/H-L1
31-40	MT6/H-31-40	L2	MT6/H-L2
41-50	MT6/H-41-50	L3	MT6/H-L3
51-60	MT6/H-51-60	N	MT6/H-N
61-70	MT6/H-61-70	R	MT6/H-R
71-80	MT6/H-71-80	S	MT6/H-S
81-90	MT6/H-81-90	X	MT6/H-X
91-100	MT6/H-91-100	Y	MT6/H-Y
101-110	MT6/H-101-110	Z	MT6/H-Z
111-120	MT6/H-111-120	Ground Symbol	MT6/H-GRND
121-130	MT6/H-121-130		

VERTICAL

Imprint	Cat. No.	Imprint	Cat. No.
1	MT6/V-1	131-140	MT6/V-131-140
2	MT6/V-2	141-150	MT6/V-141-150
3	MT6/V-3	151-160	MT6/V-151-160
4	MT6/V-4	161-170	MT6/V-161-170
5	MT6/V-5	171-180	MT6/V-171-180
6	MT6/V-6	181-190	MT6/V-181-190
7	MT6/V-7	191-200	MT6/V-191-200
8	MT6/V-8	1-100	MT6/V-1-100
9	MT6/V-9	1-50	MT6/V-1-50
10	MT6/V-10	A	MT6/V-A
1-10	MT6/V-1-10	B	MT6/V-B
11-20	MT6/V-11-20	C	MT6/V-C
21-30	MT6/V-21-30	L1	MT6/V-L1
31-40	MT6/V-31-40	L2	MT6/V-L2
41-50	MT6/V-41-50	L3	MT6/V-L3
51-60	MT6/V-51-60	N	MT6/V-N
61-70	MT6/V-61-70	R	MT6/V-R
71-80	MT6/V-71-80	S	MT6/V-S
81-90	MT6/V-81-90	X	MT6/V-X
91-100	MT6/V-91-100	Y	MT6/V-Y
101-110	MT6/V-101-110	Z	MT6/V-Z
111-120	MT6/V-111-120	Ground Symbol	MT6/V-GRND
121-130	MT6/V-121-130		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[MT8/H-1-10](#) [MT8/H-11-20](#) [MT8/H-21-30](#) [MT9/V-111-120](#) [MT8/H-1-100](#) [MT9/V-31-40](#) [MT6/V-L](#) [MT2/V-0](#) [MT2/V-1](#)
[MT2/V-6](#) [MT8/V-1-100](#) [MT5/V-11](#) [MT5/V-12](#) [MT2/V-1-100](#) [MT2/V-7](#) [MT4/V-1-10](#) [MT4/V-11-20](#) [MT4/V-21-30](#)
[MT5/V-301-310](#) [MT5/V-311-320](#) [MT5/V-321-330](#) [MT5/V-GND](#) [MT6/V-1-100](#) [MT6/V-1-200](#) [MT6/V-D](#) [MT6/V-F](#)
[MT8/V-L](#) [MT2/V-15](#) [MT2/V-1-50](#) [MT2/V-251-260](#) [MT2/V-261-270](#) [MT2/V-271-280](#) [MT2/V-291-300](#) [MT2/V-301-310](#)
[MT2/V-311-320](#) [MT2/V-321-330](#) [MT2/V-331-340](#) [MT2/V-341-350](#) [MT2/V-351-360](#) [MT2/V-361-370](#) [MT2/V-371-380](#)
[MT2/V-391-400](#) [MT2/V-401-410](#) [MT2/V-441-450](#) [MT2/V-45](#) [MT2/V-451-460](#) [MT2/V-491-500](#) [MT2/V-501-510](#)
[MT2/V-511-520](#) [MT2/V-541-550](#) [MT2/V-551-560](#) [MT2/V-561-570](#) [MT2/V-591-600](#) [MT2/V-601-610](#) [MT2/V-611-620](#)
[MT2/V-621-630](#) [MT2/V-631-640](#) [MT2/V-641-650](#) [MT2/V-651-660](#) [MT2/V-661-670](#) [MT2/V-S](#) [MT4/V-101-110](#) [MT4/V-](#)
[111-120](#) [MT4/V-31-40](#) [MT4/V-41-50](#) [MT4/V-51-60](#) [MT4/V-61-70](#) [MT4/V-71-80](#) [MT4/V-81-90](#) [MT4/V-91-100](#) [MT6/V-](#)
[28](#) [MT6/V-G](#)