 

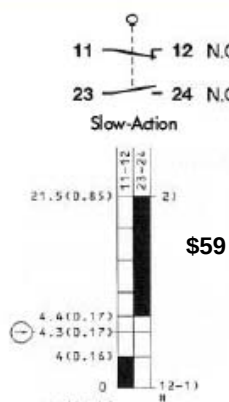
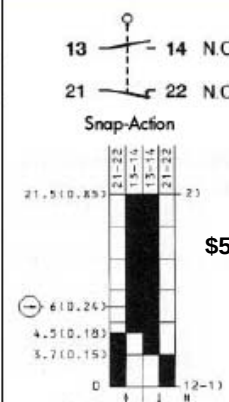
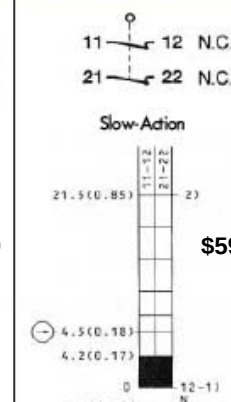


INTERLOCK SWITCH - SKT

SPECIFICATIONS	KEY FEATURES	2 POLE
NEMA 4, 12 2 Pole 10 ⁶ Mechanical Operations 10 Amp 250V AC -22° F + 176° F min/max temp. 11 lbs. Door Holding Force 10mA min. current Key Entry Rotates 4 x 90° Cable Entry Thread M16 x 1.5 + 1/2" NPT UL, CSA, CE, BG, IEC 947-5-1 BG Safety Agency Approved	• Eight key entry locations★ • Screw Terminals • Quick Connect Option • Glass Reinforced Thermoplastic • Positive Opening N.C. contact → • Tamper Resistant • 2" Min. Closing Radius "MRU" key, Die Cast Aluminum • Stainless Steel M-3 key, 6" min. Closing Radius	Narrow Profile for Confined Spaces  SKT Series Actuator keys sold separately. See page 4.
★ Switch head rotates, permits <u>four different side</u> and <u>four top</u> key entry locations.		

Part #	601.6419.146 SKT-U1Z-F150 M3	601.6409.150 SKT-SUIZ-F150 M3	601.6469.148 SKT-A2Z-F150 M3	601.6467.067 SKTS-A2Z-F150-M3
Contact layout → (with key inserted)  Contact travel mm (inch) Tol. ± 0.25 mm Switch angle degree Tol. ± 3.5° In Out Actuating force N Tol. ± 10% Actuating torque Ncm Tol. ± 10% *) actuator in *) actuator out	11 12 N.C. 23 24 N.O. Slow-Action  \$59	13 14 N.O. 21 22 N.C. Snap-Action  \$59	11 12 N.C. 21 22 N.C. Slow-Action  \$59	11 12 N.C. 21 22 N.C. Slow-Action  \$59

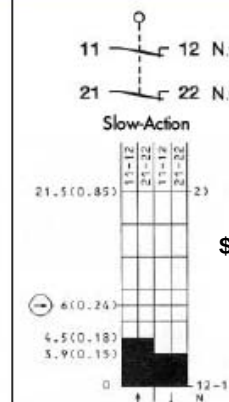

Quick Connect Option:
See page 25.
For Plug and Socket options.



Metal 1/2" NPT Option:
Non-Metal 1/2" NPT adaptor supplied standard.
For Metal Adaptor, add "ME" to part #.
Example: SK-UV15ZF30M-ME
(no extra charge)



Cord Grip Cable Gland Option:
Add "GRIP" to part # to replace the standard M16 to 1/2" NPT Adaptor.
For 3mm to 10mm cable diameter
Example: SKT-U1Z-GRIP
(no extra charge)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[601.6409.150](#) [601.6469.148](#)