

RECEPTACLES

Features:

- DIN Rail, Panel Mount or Wall Mount
- Rating: 16A/250V AC
- Finger Protection: IP20
- Available in 3 colors.


PANEL MOUNT



WALL MOUNT






DIN RAIL MOUNT

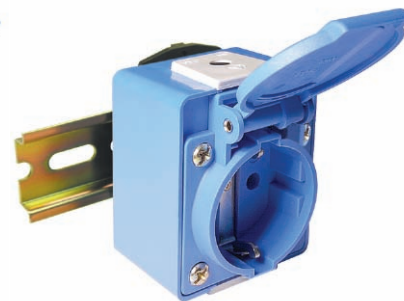

External Dimension (HxWxL mm)	36.5 x 61.5 x 50	50 x 71 x 53.5	58.5 x 84 x 53.5
Stripping Length	10 mm	10 mm	10 mm
Insulation Material	Thermoplastic	Thermoplastic	Thermoplastic
Type of Connection	3 screw clamps	3 screw clamps	3 screw clamps
Standard	DIN 49440	DIN 49440	DIN 49440
Voltage Rating	250 V	250 V	250 V
Current Rating	16 A	16 A	16 A

	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Complete Kit:						
Blue	PMRBU-GE	1	WMRBU-GE	1	DMRBU-GE	1
Gray	PMRGR-GE	1	WMRGR-GE	1	DMRGR-GE	1
Black	PMRBA-GE	1	WMRBA-GE	1	DMRBA-GE	1
Optional Accessory						
Sealing Gasket	SEALGASK	1	SEALGASK	1	SEALGASK	1

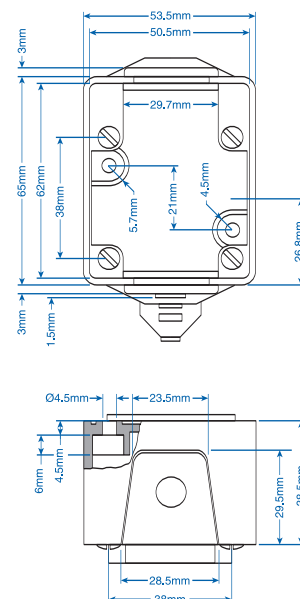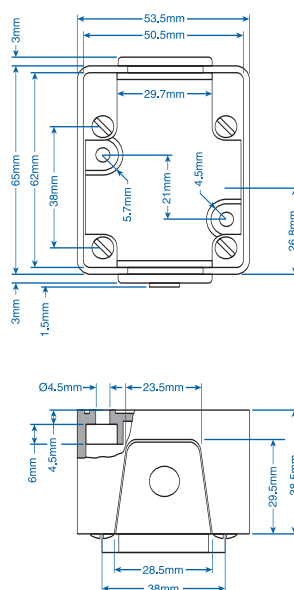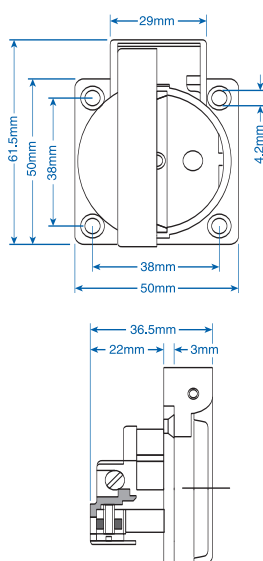

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[PMRBA-GE](#)