

Accessories

Manual Motor Starter
- MMS Series



UL508 Type E
E252942

Altech Corp.



Extended Handles

- Lockable in ON/ OFF position
- IP65 protection

Part No.	MMS-Type	Shaft Length
MEH-32-115	MMS-32H	115mm (4.53in.)
MEH-32-315	MMS-32H	315mm (12.4in.)
MEH-63-115	MMS-63H	115mm (4.53in.)
MEH-63-315	MMS-63H	315mm (12.4in.)
MEH-100-115	MMS-100H	115mm (4.53in.)
MEH-100-315	MMS-100H	315mm (12.4in.)



Busbars

Part No.	MMS Type	No, MMS	Rated Current
PB-322	MMS-32H	2	63A
PB-323	MMS-32H	3	63A
PB-632	MMS-63H	2	108A
PB-633	MMS-63H	3	108A

Insulation Cap

Part No.	Busbar Type
PBPC-32	PB-32x
PBPC-63	PB-63x



Insulated Enclosure

- IP65 protection

Part No.	MMS Type
EPH-32	MKMS-32H



Dial Cover



Dial Cover


to protect set value
from unintended operation
(for all types)

Part No.
DIAL COVER

Insulation Barrier

to increase creepage
and clearance distance
(for MMS-100H only)

Part No.
IB100

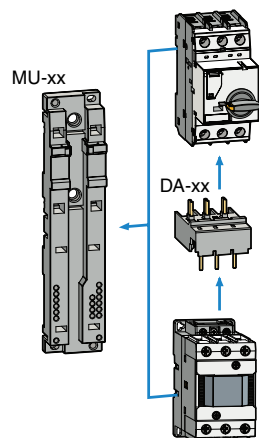

Direct Adapters and Mounting Units

- Connect MMS directly with Metasol or Mini Contactor
- Type F combination Motor Controllers consisting of Type E MMS device with MC Series contactor

Part No.	MMS Type	Combined Contactor Type	Mounting Unit
DA-16HA	MMS-32H	Mini Contactor GMC-6M...12M AC	MU-45
DA-16HD	MMS-32H	Mini Contactor GMC-6M...12M AC	MU-45
DA-22HA	MMS-32H	MC-9B...22B AC	MU-45
DA-22HD	MMS-32H	MC-9B...22B DC	MU-45
DA-32HA	MMS-32H	MC-32A...40A AC	MU-45
DA-32HD	MMS-32H	MC-32A...40A DC	MU-45
DA-63A	MMS-63H	MC-50A...65A AC	MU-55
DA-63D	MMS-63H	MC-50A...65A DC	MU-55
DA-95A	MMS-100H	MC-75A...100A AC	MU-70
DA-95D	MMS-100H	MC-75A...100A DC	MU-70

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[MEH-63-115](#) [MEH-32-115](#) [MEH-32-315](#) [DA-63D](#) [DA-95D](#) [DA-16HD](#) [DA-32HD](#) [IB100](#) [DIAL COVER](#) [PB-633](#)
[MEH-63-315](#) [EPH-32](#) [PB-323](#) [MEH-32-115R](#) [PB-322](#) [PBPC-32](#) [DA-16HA](#) [DA-22HA](#) [MEH-100-115](#) [MEH-100-315](#)
[DA-32HA](#) [PB-632](#) [DA-22HD](#) [DA-95A](#) [DA-63A](#) [PBPC-63](#)