

Standard Features

- **Protection Level:** IP55
- **Technical:**
  - Metric - Inlets
  - 7 x M20 - Sides
  - 1 x M16 - Rear
  - 7 Installed M20 Entry Seals
  - (5 - 16mm)
  - Snap-on Cover
- **Enclosure Material:** Semi - Rigid Polypropylene
- **Material**
  - Temperature Range:** -30°C to 100°C (-22°F to 212°F)
- **Gasket Material:** None / Contact Labyrinth Seal
- **Color:** Light Gray
- **Accessories:** See section below




HP

| Ordering Information | Cat. No. | Type | Length          | Dimensions mm (in)<br>Width | Height          | Std. Pk. |
|----------------------|----------|------|-----------------|-----------------------------|-----------------|----------|
| Enclosure            | 322-980  | HP80 | 85 mm (3.35 in) | 85 mm (3.35 in)             | 42 mm (1.65 in) | 10       |

Accessories

| Ordering Information       | Cat. No. | Type                        | Std. Pk. |
|----------------------------|----------|-----------------------------|----------|
| Terminal                   | 460-525  | 2.5mm <sup>2</sup> - 5 pole | 10       |
| Universal Entry Seal - M20 | 216-420  | M20                         | 100      |

For Liquid Tight Strain Reliefs please refer to catalog pages 150-152.

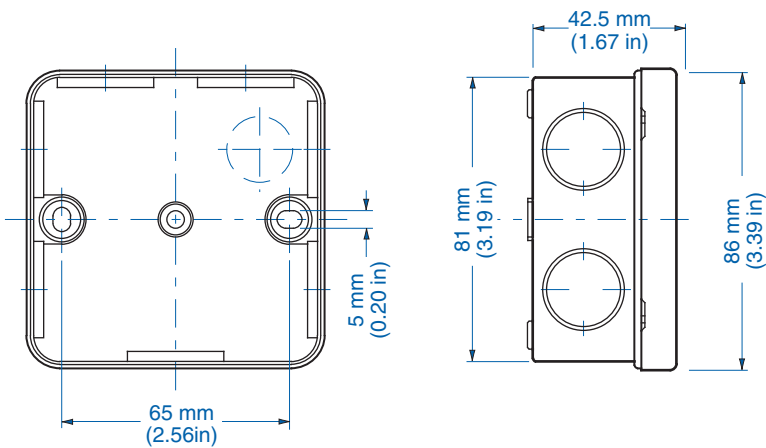

M16



M20



M20/25



M25/32




M32/40



M40/50

Knockout  
Detail

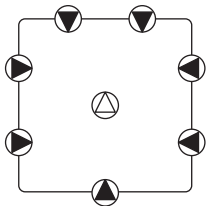

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[322-980](#)