

## TG3023-9 – ABS and Polycarbonate – 302 x 232 x 90 mm (11.89 x 9.13 x 3.54 in.)

### Standard Features

- **Protection Level:** IP67 (NEMA 4X)
- **Technical:** Smooth Sidewalls  
Gray or Transparent Cover  
Standard or Quick Turn Screws  
275 x 205 x 0.4 mm Recess in Cover  
Integrated Cover Retainer
- **UL Recognized Enclosure Materials:** ABS or Polycarbonate
- **Transparent Cover Material:** Polycarbonate
- **Gasket Material:** Polyurethane
- **Color:** Light Gray
- **Material Temperature Range:** ABS  
-40°C to 80°C (-40°F to 176°F)  
Polycarbonate  
-40°C to 120°C (-40°F to 248°F)
- **Accessories:** See section below




### TG

| Ordering Information | Cat. No.<br>w/ Standard Screws | Cat. No.<br>w/ Quick Turn Screws | Type           | Length             | Dimensions mm (in)<br>Width | Height           | Std. Pk. |
|----------------------|--------------------------------|----------------------------------|----------------|--------------------|-----------------------------|------------------|----------|
| <b>ABS</b>           |                                |                                  |                |                    |                             |                  |          |
| Gray cover           | 100-413-91                     | 100-413-01                       | TGABS3023-9-o  | 302 mm (11.89 in.) | 232 mm (9.13 in.)           | 90 mm (3.54 in.) | 1        |
| Transparent cover    | 101-013-91                     | 101-013-01                       | TGABS3023-9-to | 302 mm (11.89 in.) | 232 mm (9.13 in.)           | 90 mm (3.54 in.) | 1        |
| <b>Polycarbonate</b> |                                |                                  |                |                    |                             |                  |          |
| Gray cover           | 200-413-91                     | 200-413-01                       | TGPC3023-9-o   | 302 mm (11.89 in.) | 232 mm (9.13 in.)           | 90 mm (3.54 in.) | 1        |
| Transparent cover    | 201-013-91                     | 201-013-01                       | TGPC3023-9-to  | 302 mm (11.89 in.) | 232 mm (9.13 in.)           | 90 mm (3.54 in.) | 1        |

### Accessories

| Ordering Information     | Cat. No. | Type       | Std. Pk. |
|--------------------------|----------|------------|----------|
| Mounting Plate (plastic) | 186-013  | TGMPI-3023 | 1        |
| Mounting Plate (steel)   | 187-013  | TGMPS-3023 | 1        |
| DIN Rail – TS35-285      | 198-285  | NS35-285   | 1        |
| DIN Rail - TS15-285      | 197-285  | TS15-285   | 1        |
| Internal Hinge Kit Set   | 182-001  | TGISS      | 1        |
| Mounting Tab Kit         | 182-002  | TGABL      | 1        |

Please refer to pages 149-152 additional accessories and detailed information

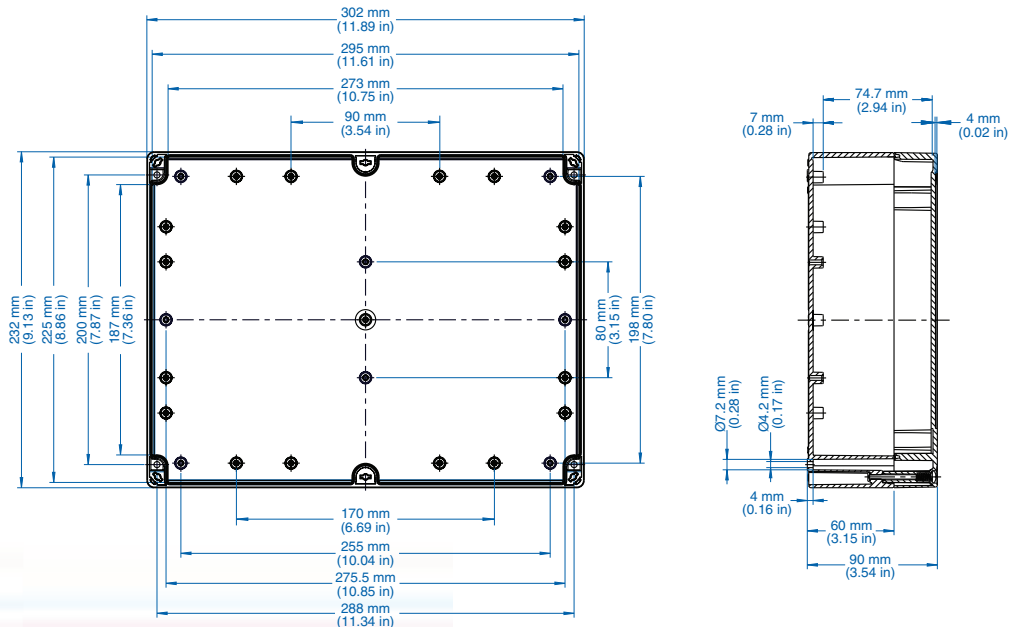

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[101-013-01](#) [100-413-91](#) [200-413-91](#) [100-413-01](#) [201-013-91](#) [200-413-01](#) [101-013-91](#) [201-013-01](#)