

 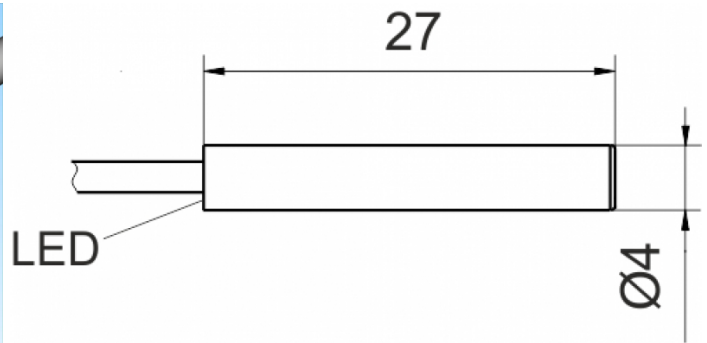


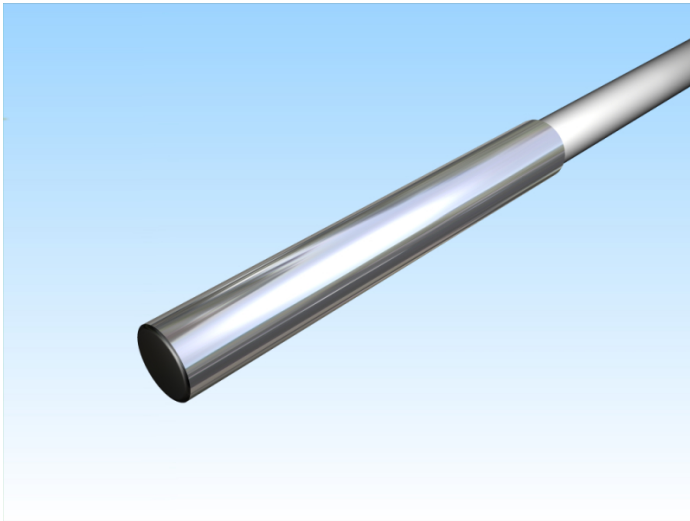

Name  
Order number  
Matchcode  
Switching distance  
Mounting

 
KJ0,8-G4EB27-DPÖ  
08317801410  
9980-1410  
0,8 mm




Switch type



Signal Type  
Connection



Connection diagramm

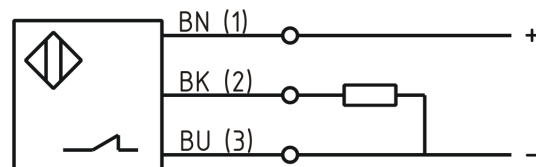

D 4 x 27

Dimension (in mm)  
Technical Specification  
Operating voltage  
Max. ripple  
Voltage drop  
Max. load current  
No load current  
Leakage current  
Switching frequency  
Switching hysteresis  
Operating temperature  
Temperature drift  
Repeat accuracy  
Switching state  
Time delay  
Short-circuit proof  
Overload protection  
Reverse voltage protection  
Protection category  
EMC-level  
Housing material

10 - 30 VDC  
≤ 10 %  
2 V  
200 mA  
≤ 13 mA  
≤ 10 µA  
2000 Hz  
≤ 15 %  
-25 ° C to 70 ° C  
≤ 10 %  
≤ 5 %  
LED  
100 ms  
yes  
yes  
yes  
IP67  
DIN EN 60947-5-2:2008  
Stainless steel V2A



## KJ0,8-G4EB27-DPÖ

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

|                                  |                        |
|----------------------------------|------------------------|
| Material active face             | POM                    |
| Cable length                     | 2 m                    |
| Utilisation category             | DC 13                  |
| Cable material                   | PUR LIY11Y schwarz     |
| Nominal operating voltage        | 24 V DC                |
| Cable cross                      | 3x0.09 mm <sup>2</sup> |
| FIT / MTTF acc. to SIEMENS 29500 | 34,46 / 3312y          |

**Errors and omissions excepted**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317801410](#)