


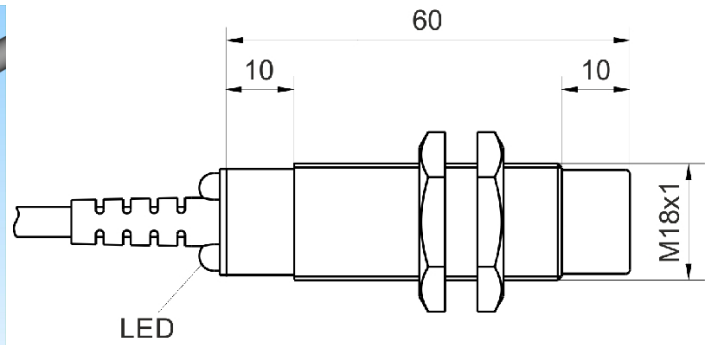

Name
Order number
art_schaltabstand_einstellbar
Switching distance
Mounting

KJ10-M18MN60-ANU-DPSS
08317144730
yes
from 0,5 mm to 10 mm

 non shielded


 Programmable
Analog Voltage

 Cable

Switch type

Signal Type
Connection

Connection diagramm

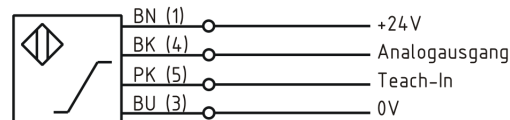

fine-pitch thread M18 x 60

Dimension (in mm)
Technical Specification
Special features

analog Output with two additional teachable digital
switching points

11 - 30 V DC
 $\leq 5 \%$
3 V
 $\leq 10 \text{ mA}$
200 Hz
-25 ° C to 70 ° C

+/-8 %
 $\leq 1 \%$
 $\leq 3 \%$

300 ms

IP67

DIN EN 60947-5-7:2004-06

Brass, nickel plated

PA 6.6

2 m

DC 13

PVC LIYY grau (grey)

24 V DC

4x0,34 mm²

Operating voltage
Max. ripple
Voltage drop
No load current
Switching frequency
Operating temperature
Temperature drift
Repeat accuracy
Linearity
Time delay
Protection category
EMC-level
Housing material
Material active face
Cable length
Utilisation category
Cable material
Nominal operating voltage
Cable cross



KJ10-M18MN60-ANU-DPSS

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

FIT / MTTF acc. to SIEMENS 29500

334,07 / 342y

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317144730](#)