
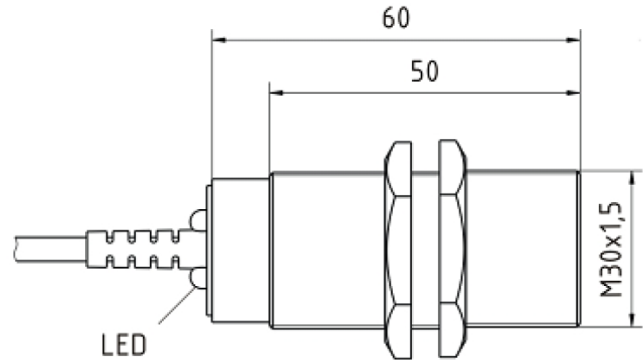


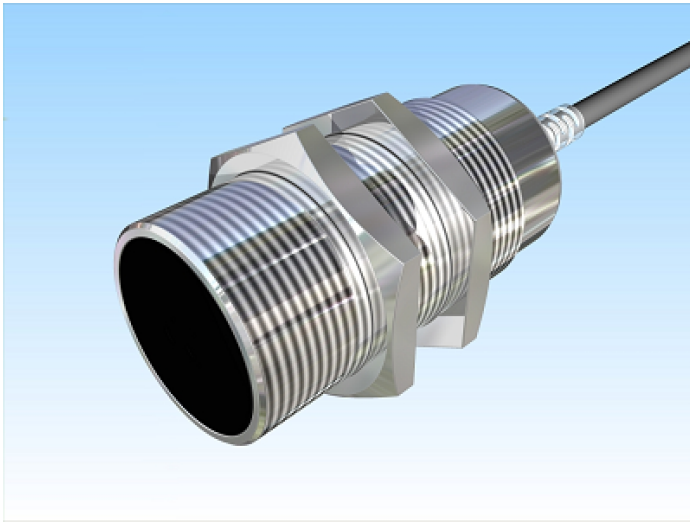

Name
Order number
Switching distance
Mounting

KJ10-M30MB60-VZS
08317171200
10 mm

 shielded


Switch type

 N.O.
AC/DC

Signal Type
Connection

 Cable

Connection diagramm

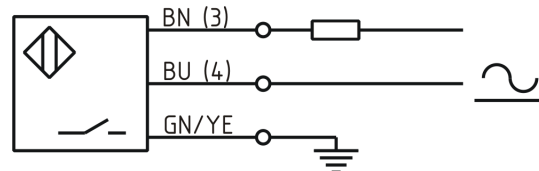

Dimension (in mm)
Technical Specification
Operating voltage
Voltage drop
Max. load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Material active face
Termination
Notes

fine-pitch thread M30 x 60

20 - 250 V AC/DC

5 V

350 mA

≤ 1,7 mA

30

≤ 15 %

-25 ° C to 70 ° C

≤ 10 %

≤ 5 %

LED

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

PCB

2m PVC 3x0,5mm²

Kurzschluss- und Überlastungsschutz rastend. Nach Beseitigung des Kurzschlusses muß die Spannungsversorgung für ca. 2s unterbrochen



KJ10-M30MB60-VZS

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

werden.

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317171200](#)