

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

inductive sensor analogue
KJ14-M12MN60-ANI-V2
08310001033
from 0,5 mm to 4 mm

 non shielded


 analog
analog current

 Connector

Switch type

Signal Type
Connection

Connection diagramm

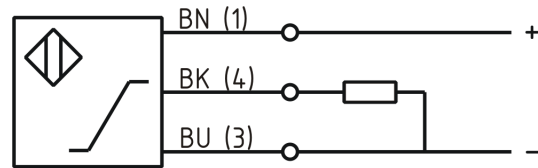

fine-pitch thread M12 x 60

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
No load current
Switching frequency
Operating temperature
Temperature drift
Repeat accuracy
Linearity
Analog output
Digital output
Protection category
EMC-level
Material active face
Termination

10 - 35 VDC
 $\leq 10 \%$
 $\leq 10 \text{ mA}$
450
-25 ° C to 70 ° C
 $\pm 5 \%$
 $\leq 1 \%$
 $\leq 5 \%$
Pulso_has1

IP67
DIN EN 60947-5-7:2004-06
PCB
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310001033](#)