
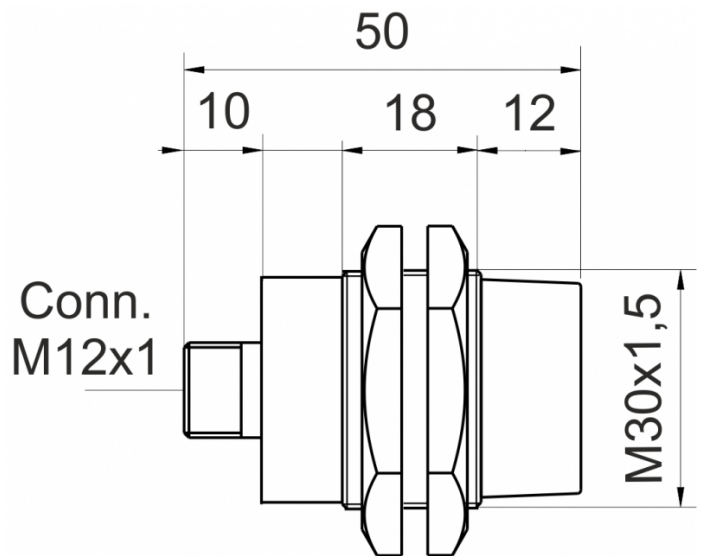


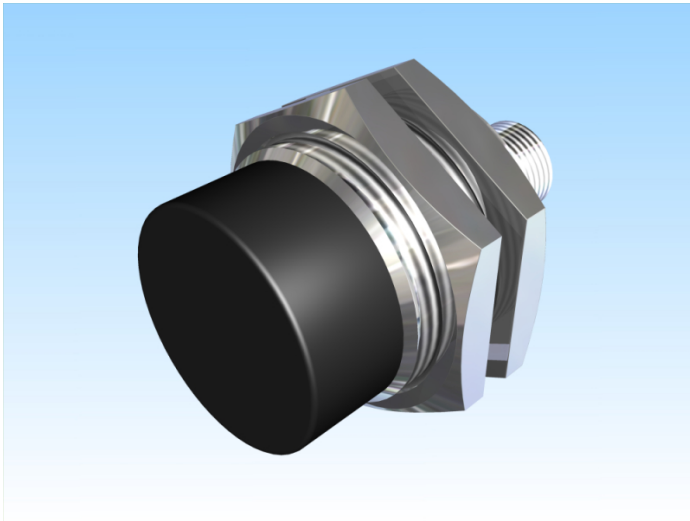


Name  
Order number  
Switching distance  
Mounting

KJ15-M30MN50-ANU-V2  
08317144665  
from 3 mm to 15 mm

 non shielded

 analog  
Analog Voltage  
connector M12

Switch type  
  
Signal Type  
Connection  
Connection diagramm

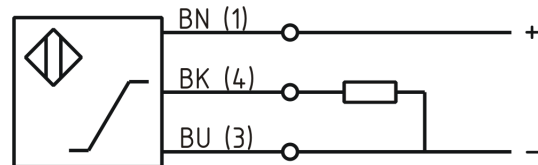

fine-pitch thread M30 x 50

Dimension (in mm)  
Technical Specification  
Special features  
Operating voltage  
Max. ripple  
No load current  
Switching frequency  
Operating temperature  
Temperature drift  
Repeat accuracy  
Linearity  
Analog output  
Time delay  
Protection category  
EMC-level  
Housing material  
Material active face  
Utilisation category  
Contact material  
Contact surface material  
Contact holder  
Nominal operating voltage

Output Voltage 1 ... 9 Volt  
11 - 35 VDC  
 $\leq 10 \%$   
 $\leq 5 \text{ mA}$   
150 Hz  
-25 ° C to 70 ° C  
 $\pm 5 \%$   
 $\leq 1 \%$   
 $\leq 5 \%$   
Pulso\_has1 (Gradient 0,67V / mm)  
300 ms  
IP67  
DIN EN 60947-5-7:2004-06  
Brass, nickel plated  
PCB  
DC 13  
CuSn  
NiAu  
PA 6  
24 V DC



## KJ15-M30MN50-ANU-V2

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Termination

Connector M12 4pin

**Errors and omissions exceptet**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317144665](#)