

 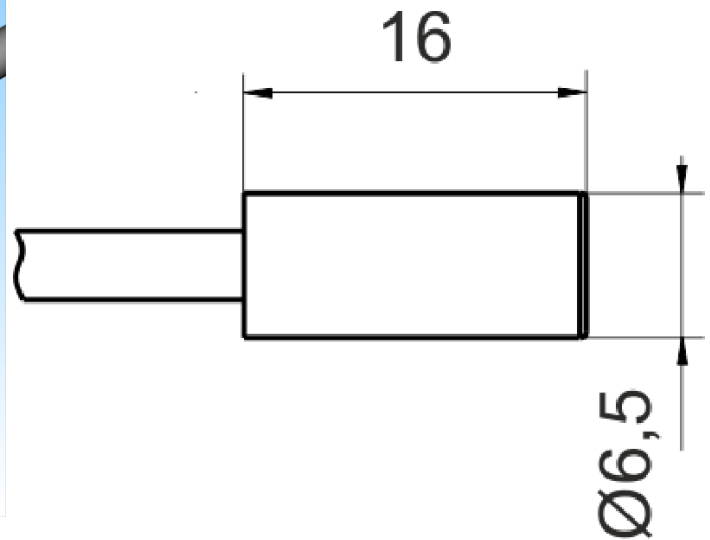


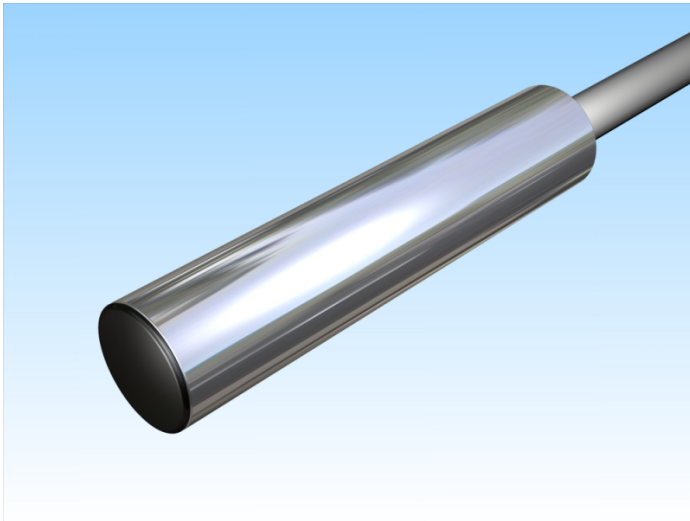

Name
Order number
Switching distance
Mounting

KJ2-G6,5EB16-DNÖ
08313650240
2 mm



shielded

Switch type



N.C.


Signal Type
Connection

DC NPN



Cable

Connection diagramm

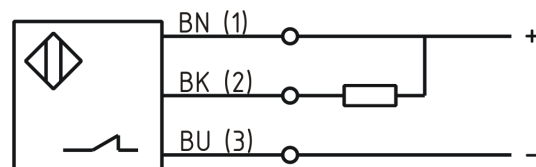

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Cable length

D 6,5 x 16
10 - 30 VDC
 $\leq 10 \%$
2,4 V
200 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
2000 Hz
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
yes
yes
yes
IP67
DIN EN 60947-5-2: 2008
Stainless steel V2A
2 m



KJ2-G6,5EB16-DNÖ

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Utilisation category
Cable material
Cable cross

DC 13
PVC grau LIYY
3x0.14 mm²

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313650240](#)