


[Article Page](#)

Product Description

inductive sensor DC

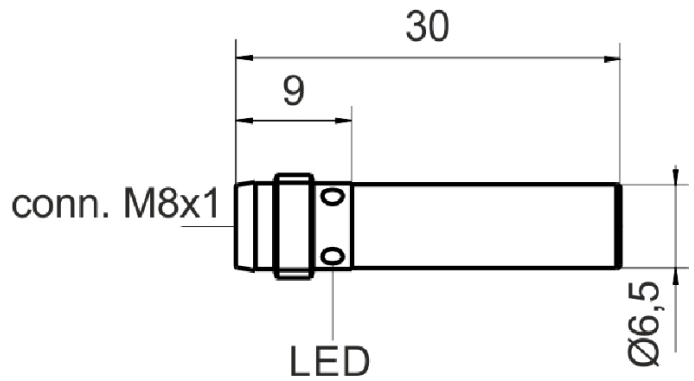

Name
Order number
Switching distance
Mounting


Switch type

Signal Type
Connection
Connection diagramm

KJ2-G6,5EB30-DPÖ-V1
08313650221
2 mm

 shielded

 N.C.
DC PNP
connector M8

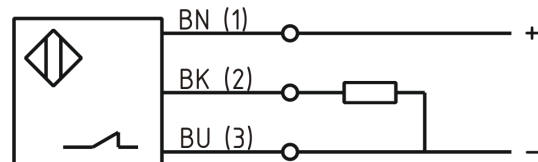

D 6,5 x 30

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
EMC-level
Housing material
Utilisation category
Termination

10 - 30 VDC
≤ 10 %
2,4 V
200 mA
≤ 10 mA
≤ 10 µA
2000 Hz
15 %
-25 ° C to 70 ° C
10 %
LED
yes
yes
yes
DIN EN 60947-5-2: 2008
Stainless steel V2A
DC 13
Connector M8 3pin

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313650221](#)