


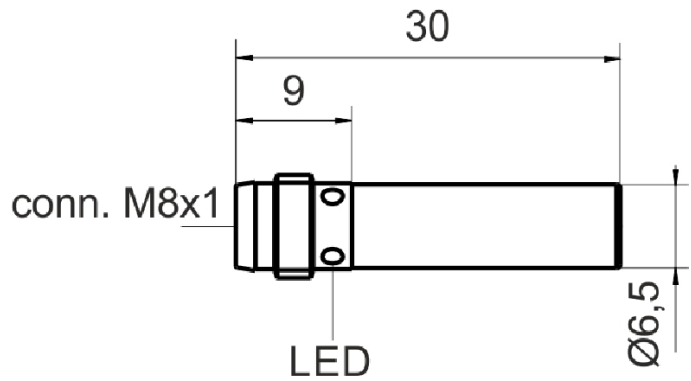

Name
Order number
Switching distance
Mounting

Switch type


Signal Type
Connection
Connection diagramm

KJ2-G6,5EB30-DPS-V1
08313650211
2 mm

 shielded

 N.O.
DC PNP
connector M8

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Utilisation category
Termination

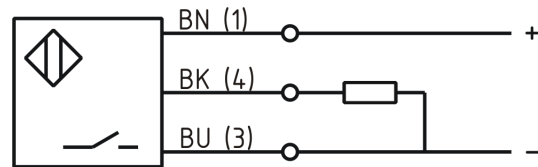

D 6.5 x 30

10 - 30 VDC
≤ 10 %
1 V
200 mA
≤ 10 mA
≤ 10 µA
2000 Hz
≤ 15 %
-25 ° C to 70 ° C
≤ 10 %
≤ 5 %
LED
yes
yes
yes
IP 67
DIN EN 60947-5-2: 2008
Stainless steel V2A
DC 13
Connector M8 3pin



KJ2-G6,5EB30-DPS-V1

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313650211](#)