
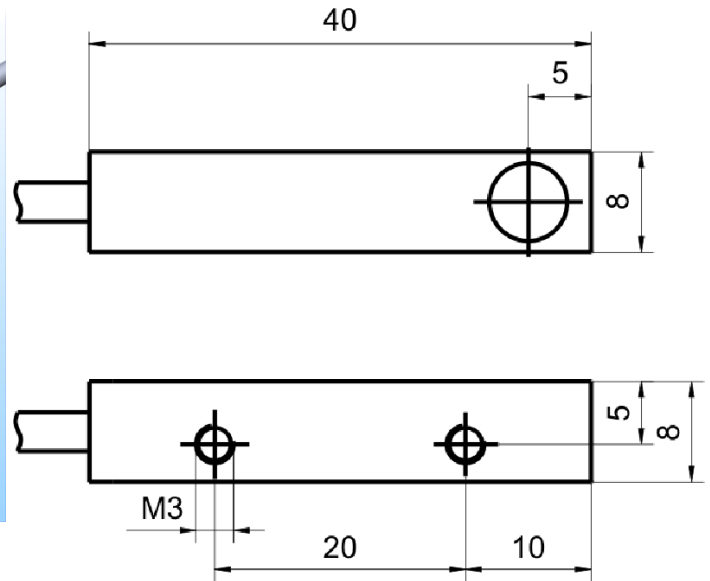


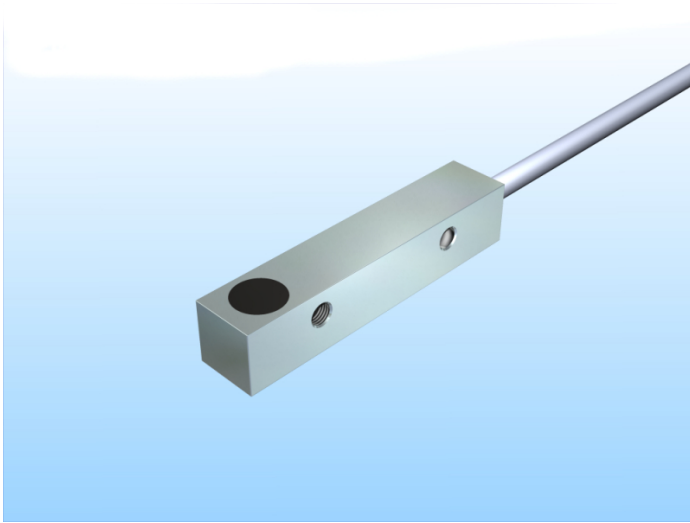

Name
Order number
Switching distance
Mounting

KJ2-Q8MB-DPS
08310000475
2 mm

 shielded


Switch type

 N.O.
DC PNP

Signal Type
Connection

 Cable

Connection diagramm

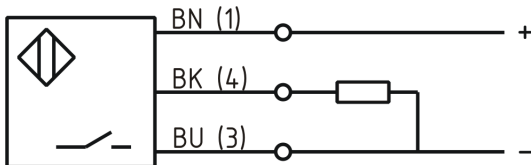

Q 8 x 8 x 40

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Time delay
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level

10 - 30 VDC
 $\leq 10 \%$
2,4 V
200 mA
 $\leq 13 \text{ mA}$
 $\leq 10 \mu\text{A}$
1000 Hz
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
100 ms
yes
yes
yes
IP67
DIN EN 60947-5-2:2008



KJ2-Q8MB-DPS

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Housing material
Material active face
Cable length
Utilisation category
Cable material
Cable cross
FIT / MTTF acc. to SIEMENS 29500

Brass, nickel plated
Ultramid schwarz (black)
2 m
DC 13
PVC LIYY grau (grey)
3x0.14 mm²
48,19 / 2369y

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310000475](#)