

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

Switch type

Signal Type
Connection

Connection diagramm


Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
No load current
Switching frequency
Operating temperature
Temperature drift
Repeat accuracy
Linearity
Analog output
Digital output
Protection category
EMC-level
Material active face
Termination

inductive sensor analogue
KJ3-M12MB60-ANU-V2
08317143865
from 0,25 mm to 3 mm

 shielded

 analog
Analog Voltage

 Connector

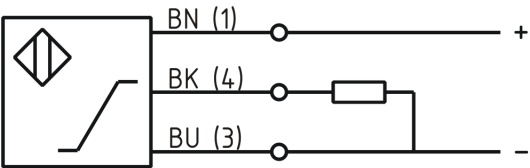

fine-pitch thread M12 x 60

11 - 35 VDC
 $\leq 10 \%$
 $\leq 5 \text{ mA}$
500
-25 ° C to 70 ° C
 $\pm 5 \%$
 $\leq 1 \%$
 $\leq 5 \%$
Pulso_has1

IP67
DIN EN 60947-5-7:2004-06
PCB
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317143865](#)