 


[Article Page](#)

Product Description
Name
Order number
Matchcode
Switching distance
Mounting

inductive sensor DC
KJ3-M8EB60-DNÖ-V1
08317815564
9981-5000
3 mm




Switch type



Signal Type
Connection



Connection diagramm

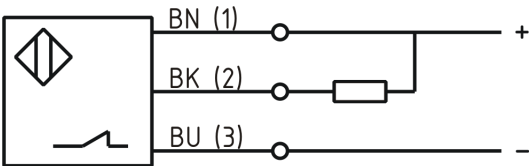

fine-pitch thread M8 x 60

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Digital output
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Material active face
Termination

10 - 30 VDC
≤ 10 %
1 V
200 mA
≤ 10 mA
≤ 10 µA
1000
≤ 15 %
-25 ° C to 70 ° C
< 10 %
≤ 2 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Stainless steel V2A
PA 6.6
Connector M8 3pol

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317815564](#)