
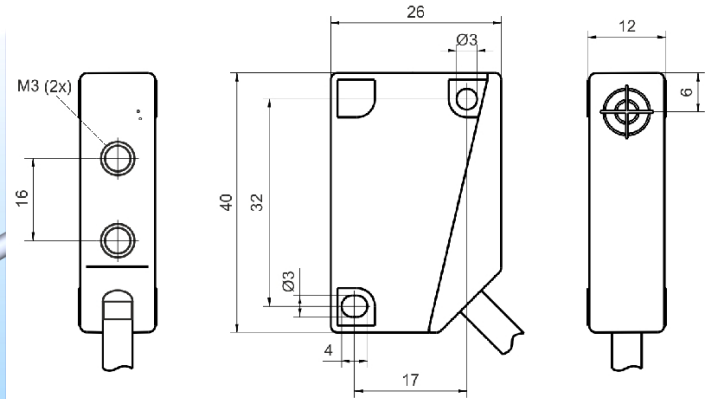


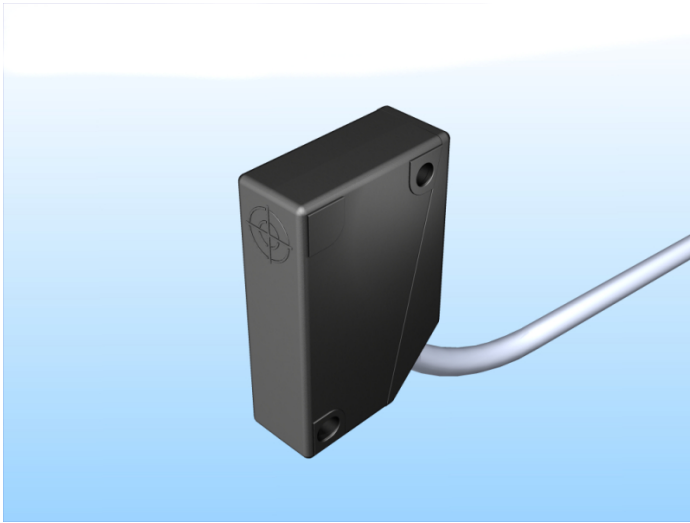

Name
Order number
Switching distance
Mounting

Switch type

Signal Type
Connection


Connection diagramm

KJ4-Q12KN-DPA
08310000527
4 mm

 non shielded

 Changeover
DC PNP

 Cable

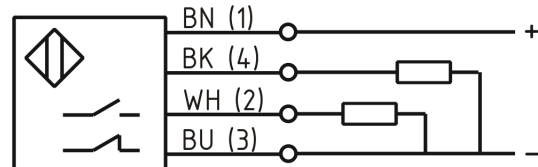

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Cable length
Utilisation category

Q 12 x 40 x 26

10 - 30 VDC
 $\leq 10 \%$
2,4 V
200 mA
 $\leq 13 \text{ mA}$
 $\leq 10 \mu\text{A}$
800
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 2 \%$
LED
yes
yes
yes
IP67
DIN EN 60947-5-2: 2008
PBT
2 m
DC 13



KJ4-Q12KN-DPA

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Cable material
Cable cross

PVC LIYY grau
4x0.34 mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310000527](#)