


[Article Page](#)

Product Description

inductive sensor AC

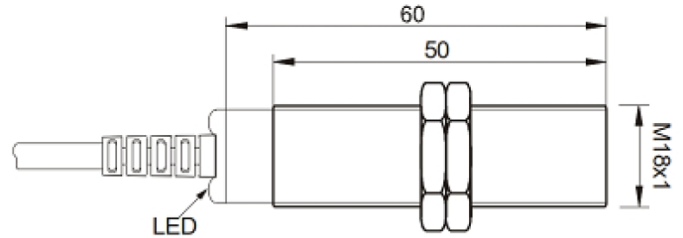

Name
Order number
Matchcode
Switching distance
Mounting

 
KJ5-M18MB60-AZS
08317211200
9921-1200
5 mm

 shielded


Switch type

 N.O.
AC

Signal Type
Connection

 Cable

Connection diagramm

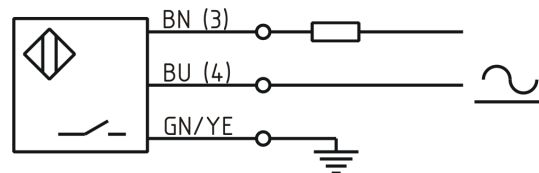

Dimension (in mm)
Technical Specification
Operating voltage
Voltage drop
Max. load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Material active face
Termination

fine-pitch thread M18 x 60

20 - 250 VAC
5 V
300 mA
 ≤ 2 mA
15
 ≤ 15 %
-25 ° C to 70 ° C
 ≤ 10 %
 ≤ 5 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
PCB
2m PVC 3x0,5mm²

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317211200](#)