


[Article Page](#)

Product Description		inductive speed limiter
Name	KJ5-M18MB80-DPI-X0130	
Order number	08310001089	
Switching distance	4 mm	
Mounting	 shielded	
Switch type	 Impuls Output	
Signal Type	DC PNP	
Connection	 Cable	

Connection diagramm

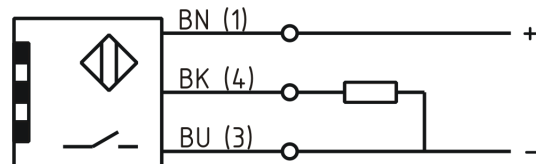

Dimension (in mm)	fine-pitch thread M18 x 80
-------------------	----------------------------

Technical Specification	
Special features	high temperature sensors
Operating voltage	10 - 36 V DC
Max. ripple	$\leq 10 \%$
Max. load current	200 mA
No load current	$\leq 30 \text{ mA}$
Leakage current	$\leq 10 \mu\text{A}$
Operating temperature	-25 ° C to 70 ° C
Temperature drift	$\leq 10 \%$
Repeat accuracy	1,0 %
Switching state	LED
Short-circuit proof	yes
Overload protection	yes
Reverse voltage protection	yes
Protection category	IP67
Material active face	PA 6.6
Notes	Drehzahlüberwachung programmierbar

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310001089](#)