
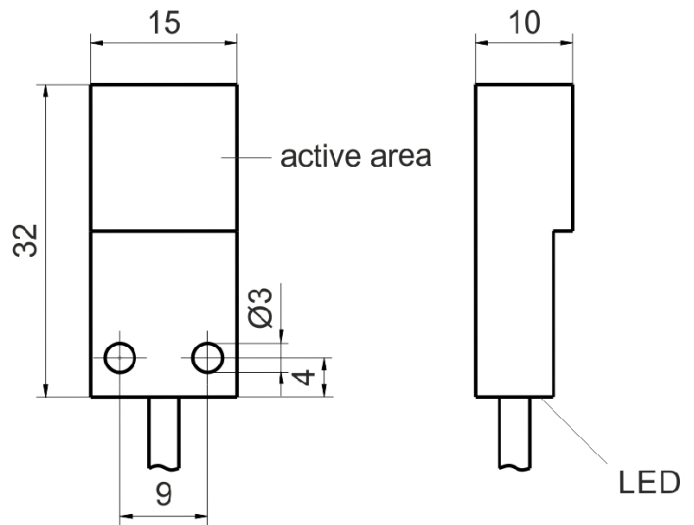


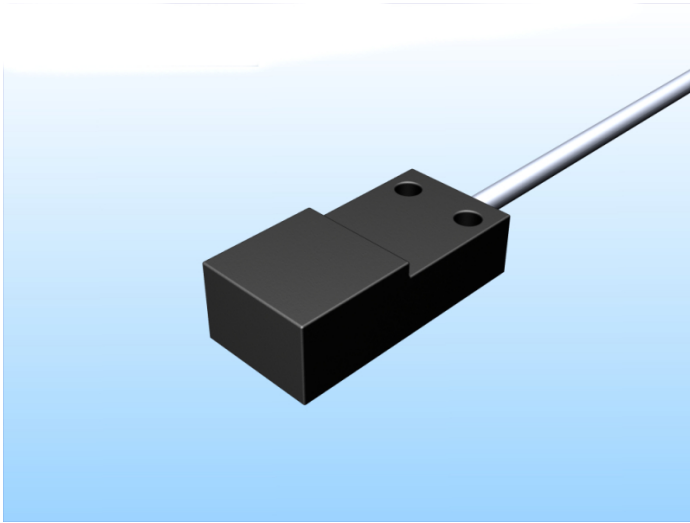

Name
Order number
Switching distance
Mounting

KJ6,4-Q15KN32-DNS
08313156430
6,4 mm

 non shielded


Switch type

 N.O.
DC NPN

Signal Type
Connection

 Cable

Connection diagramm

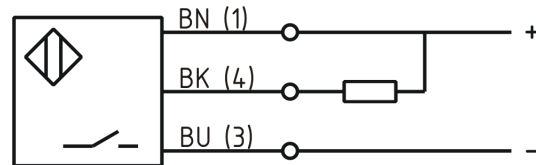

Q 15 x 10 x 32

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Cable length
Utilisation category
Cable material

10 - 30 V DC
≤ 10 %
1 V
100 mA
≤ 10 mA
≤ 10 µA
250
≤ 15 %
-25 ° C to 70 ° C
≤ 10 %
≤ 3 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2: 2008
2 m
DC 13
PVC grau LIYY



KJ6,4-Q15KN32-DNS

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Cable cross

3x01.4 mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313156430](#)