
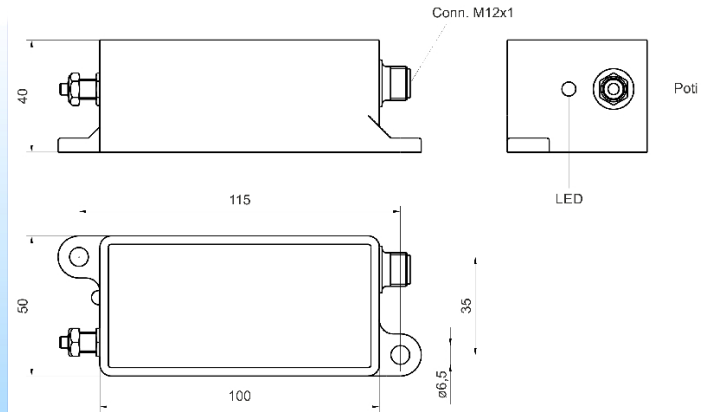


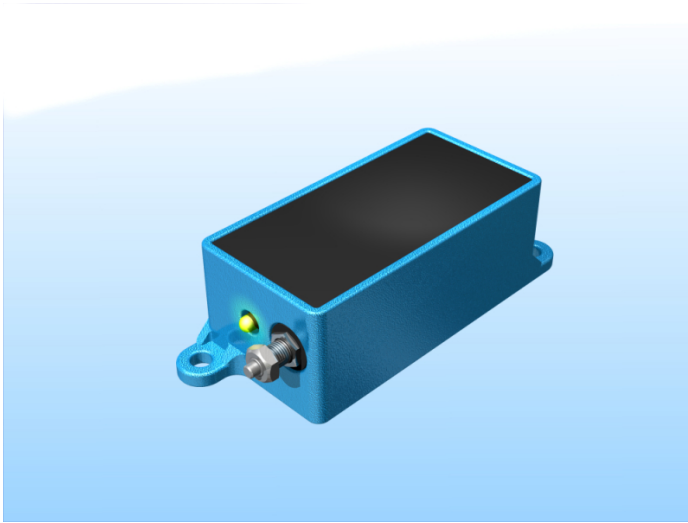

Name
Order number
Matchcode
Switching distance
Mounting

 
KJ70-Q100AN-DNS-V2-F1
08317090365
9809-0365
70 mm

 non shielded


Switch type

 N.O.
DC NPN

Signal Type
Connection

 Connector

Connection diagramm

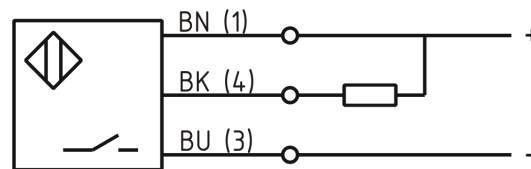

Q 100 x 50 x 40

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

10 - 30 VDC
≤ 10 %
2,4 V
400 mA
≤ 12 mA
≤ 10 μA
300
≤ 15 %
-25 ° C to 70 ° C
< 10 %
≤ 2 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Aluminum
Connector M12 4pol



KJ70-Q100AN-DNS-V2-F1

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Notes

Schaltabstand über Potentiometer einstellbar.

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08317090365](#)