


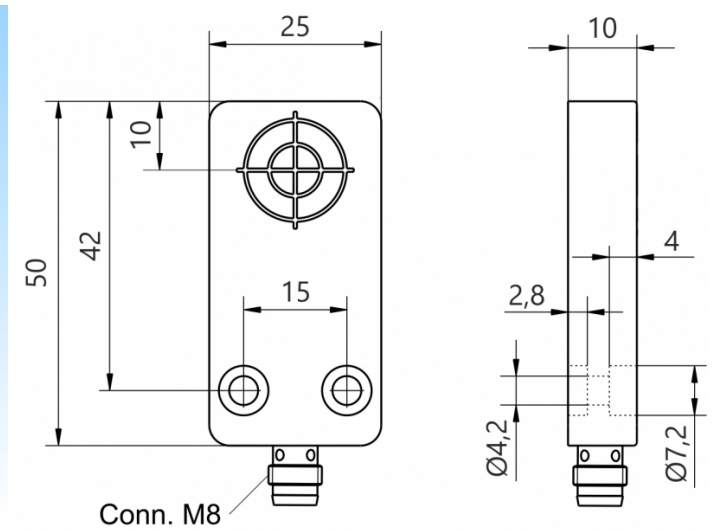

Name
Order number
Switching distance
Mounting


Switch type

Signal Type
Connection
Connection diagramm

KJ8-Q25KN-DPÖ-V1
08310001883
8 mm

 non shielded

 N.C.
DC PNP
connector M8

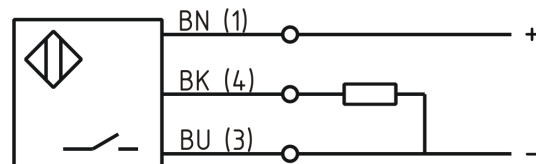

Q 25 x 10 x 50

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Utilisation category
Termination
FIT / MTTF

10 - 30 VDC
 $\leq 10 \%$
2,4 V
200 mA
 $\leq 13 \text{ mA}$
 $\leq 10 \mu\text{A}$
800
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
yes
yes
yes
IP 67
DIN EN 60947-5-2: 2008
PA 6.6
DC 13
Connector M8 3pin
90,88 / 1256y



KJ8-Q25KN-DPÖ-V1

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310001883](#)