
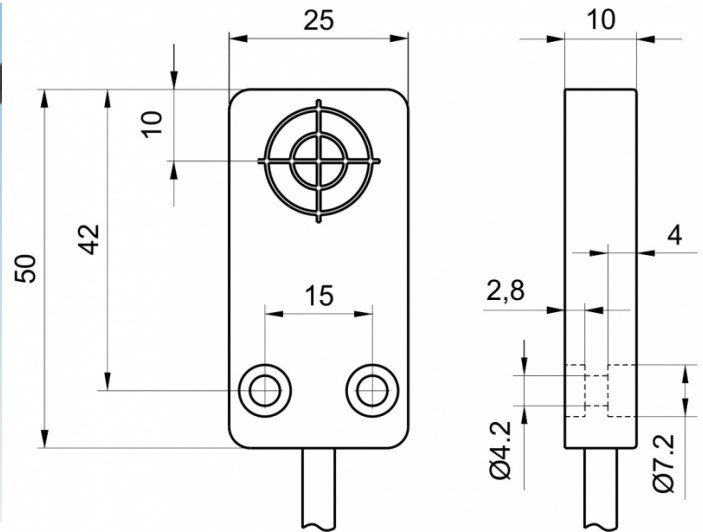


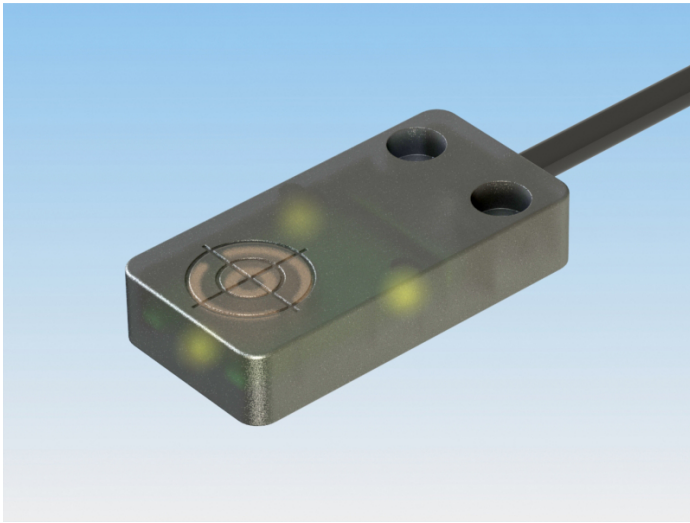

Name
Order number
Switching distance
Mounting

KJ8-Q25KN-DPA
08310001079
8 mm

 non shielded


 Changeover
DC PNP

 Cable

Switch type

Signal Type
Connection

Connection diagramm

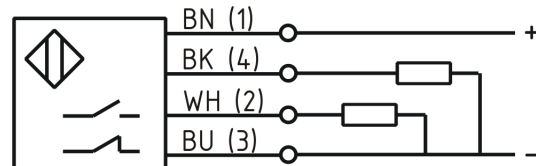

Q 25 x 10 x 50

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Cable length
Utilisation category

10 - 30 VDC
 $\leq 10 \%$
2,4 V
200 mA
 $\leq 13 \text{ mA}$
 $\leq 10 \mu\text{A}$
800 Hz
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
yes
yes
yes
IP 67
DIN EN 60947-5-2: 2008
PA 6.6
2 m
DC 13



KJ8-Q25KN-DPA

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Cable material

PVC LIYY grau

Cable cross

4x0.15 mm²

FIT / MTTF

114,77 / 995y

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08310001079](#)