

[Article Page](#)

Product Description

Name

Order number

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

laser fork light barrier

KLEG120-Q55AB-DPU-V1-RT

08373433120



Switchable


DC PNP



Laser



Connector

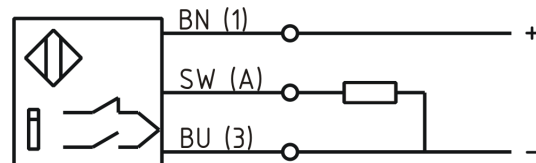

85 x 12 x 145

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Repeat accuracy

Switching state

Digital output

Fork width

Material of light outlet

Laser class

Min. object

Resolution

Sensitivity adjustable

Short-circuit proof

Protection category

Housing material

Termination

Throughbeam sensor

10 - 30 V DC

400 mA

max. 60 mA

10

-10 ° C to 60 ° C

0,01 mm

LED

120 mm

Glas

2

Ø 0,05 mm

Ø 0,05 mm

ja

yes

IP65

Aluminum

Connector M8 3pol

**Errors and omissions exceptet**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08373433120](#)