


[Article Page](#)

Product Description		laser fork light barrier
Name	KLEG180-Q114AB-DPU-V1-RT	
Order number	08373333180	
Switch type	 Switchable	
Signal Type	DC PNP	
Illuminant	 Laser	
Connection	 Connector	

Connection diagramm

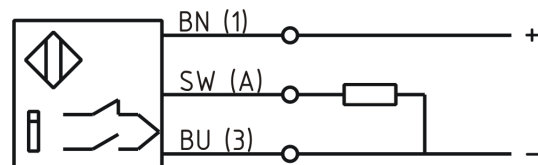

Dimension (in mm)	144 x 12 x 204
-------------------	----------------

Technical Specification	
Signal type	Throughbeam sensor
Operating voltage	10 - 35 V DC
Max. load current	200 mA
No load current	< 30 mA
Switching frequency	10
Operating temperature	-10 ° C to 60 ° C
Repeat accuracy	0,01 mm
Swiching state	LED
Digital output	
Natural extraneous light	50000 Lux
Artificial extraneous light	50000 Lux
Material of light outlet	Glas
Sensitivity adjustable	ja
Short-circuit proof	yes
Protection category	IP67
Housing material	Aluminum
Termination	Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08373333180](#)