

Article Page

Product Description
Name
Order number
Switch type

Signal Type
Illuminant
Connection


Connection diagramm

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Repeat accuracy
Switching state
Fork width
Material of light outlet
Laser class
Min. object
Resolution
Sensitivity adjustable
Short-circuit proof
Protection category
Housing material
Termination

laser fork light barrier
KLEG20-Q35AB-DPU-V1-RT
08373433020

 Switchable
DC PNP
 Laser

 Connector

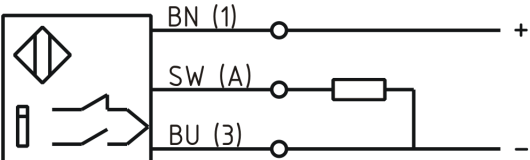

45 x 10 x 60

Throughbeam sensor
10 - 30 V DC
400 mA
max. 60 mA
10
-10 ° C to 60 ° C
0,01 mm
LED
20 mm
Glas
2
Ø 0,05 mm
Ø 0,05 mm
ja
yes
IP65
Aluminum
Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08373433020](#)