


[Article Page](#)

Product Description

laser fork light barrier

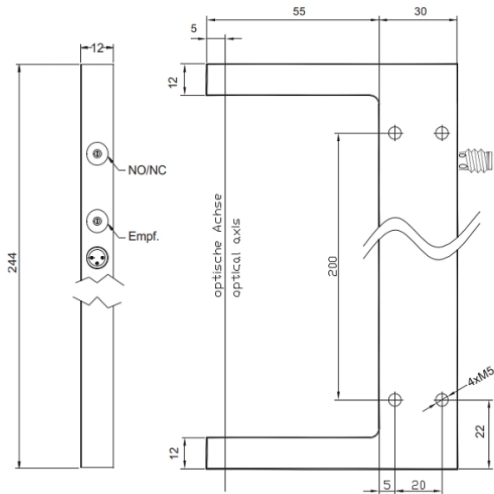

Name
Order number
Switch type


KLEG220-Q55AB-DPU-V1-RT
08373433220

 Switchable
DC PNP
 Laser

Signal Type
Illuminant
Connection

 Connector

Connection diagramm

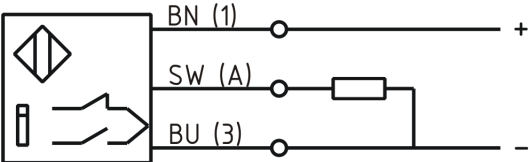

85 x 12 x 245

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Repeat accuracy
Switching state
Fork width
Material of light outlet
Laser class
Min. object
Resolution
Sensitivity adjustable
Short-circuit proof
Protection category
Housing material
Termination

Throughbeam sensor
10 - 30 V DC
400 mA
max. 60 mA
1 kHz
-10 ° C to 60 ° C
0,01 mm
LED
220 mm
Glas
2
Ø 0,05 mm
Ø 0,05 mm
ja
yes
IP65
Aluminum
Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08373433220](#)