

Article Page



Product Description
Name
Order number
Switch type

Signal Type
Illuminant
Connection

Connection diagramm

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Repeat accuracy
Switching state
Digital output
Fork width
Material of light outlet
Laser class
Min. object
Resolution
Sensitivity adjustable
Short-circuit proof
Protection category
Housing material
Termination

laser fork light barrier
KLEG80-Q55AB-DPU-V1-RT
08373433080

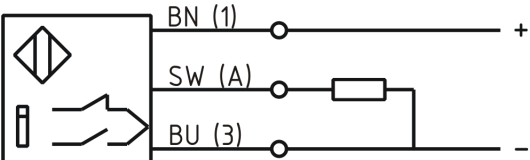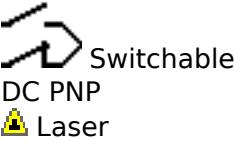

80 x 10 x 105

Throughbeam sensor
10 - 30 V DC
400 mA
max. 60 mA
10
-10 ° C to 60 ° C
0,01 mm
LED

80 mm
Glas
2
Ø 0,05 mm
Ø 0,05 mm
ja
yes
IP65
Aluminum
Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08373433080](#)