

[Article Page](#)

Product Description

Name

Order number

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

fork light barrier

KOEG220-Q60AB-DPU-V1-RT

08363533220




Switchable

DC PNP

● Red light



Connector

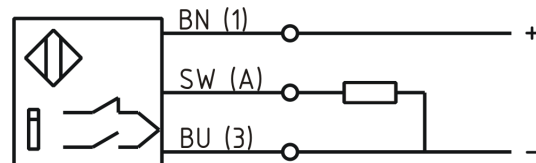

Dimension (in mm)

art_gewicht

Technical Specification

Signal type

Operating voltage

Max. load current

Switching frequency

Operating temperature

Repeat accuracy

Switching state

Digital output

Natural extraneous light

Artificial extraneous light

Material of light outlet

Sensitivity adjustable

Short-circuit proof

Protection category

EMC-level

Housing material

Termination

244 x 12 x 100

240

Throughbeam sensor

10 - 30 V DC

100 mA

3

-20 ° C to 60 ° C

0,05 mm

LED

100000 Lux

100000 Lux

Glas

ja

yes

IP67

DIN EN 60947-5-2:2008

Aluminum

Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363533220](#)