

[Article Page](#)

Product Description

Name

one-way light barrier

Order number

KOES15M-M18MB71-D-IR

Matchcode

08363250227

Illuminant


M18B-T015MD-EX9C3L2

Connection

IR Infrared light 880 nm

 Cable

Connection diagramm

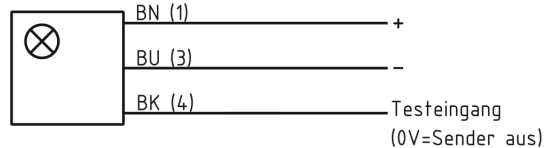

Technical Specification

Signal type

Throughbeam sensor

Operating voltage

10 - 30 V DC

Max. load current

200 mA

No load current

< 30 mA

Operating temperature

-25 ° C to 55 ° C

Digital output

Measuring range

15 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Termination

2m PVC 3x0,5mm²

Notes

Sender mit Testeingang

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363250227](#)