

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

one-way light barrier

KOES15M-M18MB85-DPU-V2-IR

08363250232

M18B-T015MP-CX9Q4UE

100110




Programmable

DC PNP

IR Infrared light 880 nm



Connector

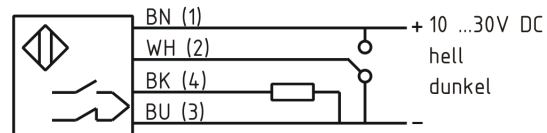

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Switching state

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Throughbeam sensor

10 - 30 V DC

200 mA

< 30 mA

300

-25 ° C to 55 ° C

LED

15 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363250232](#)