

[Article Page](#)

Product Description

Name

one-way light barrier

Order number

KOES4000-Q20KB-DPA-RT

Matchcode

08363205003

Switch type

UP-T4000P-CX6C4U2



Changeover

 
Signal Type

DC PNP

Illuminant


● Red light 660 nm

Connection



Cable

Connection diagramm

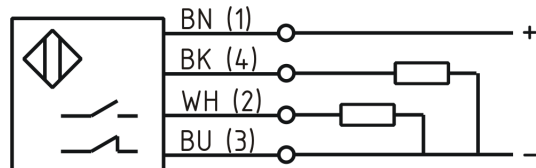

8 x 20 x 36.8

Dimension (in mm)

Technical Specification

Signal type

Throughbeam sensor

Operating voltage

10 - 30 V DC

Max. load current

150 mA

No load current

< 25 mA

Switching frequency

80

Operating temperature

-20 ° C to 55 ° C

Operating state

LED

Switching state

LED

Digital output

Measuring range

4 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Housing material

Plastic

Termination

2m PVC 3x0,15mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363205003](#)