 


[Article Page](#)

Product Description

Name
Order number
Matchcode
Switch type

one-way light barrier
KOES5200-M12MB75-DPA-V2-IR
08363245141
M12B-T5200P-CX9Q4UE




IR Infrared light 880 nm



Signal Type
Illuminant
Connection

Connection diagramm

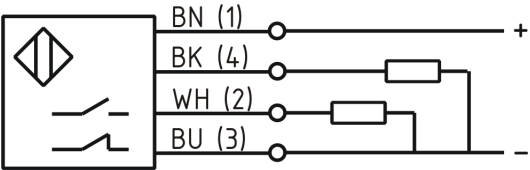

Technical Specification

Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Switching state
Digital output
Measuring range
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Termination

Throughbeam sensor
10 - 30 V DC
150 mA
< 30 mA
500
-25 ° C to 70 ° C
LED

5,2 m
ja
nein
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363245141](#)