

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

one-way light barrier

KOES60M-M30MB78-DPA-IR

08363255026

M30B-T060MP-CX9C4U2




Changeover

DC NPN

IR Infrared light 880 nm



Cable

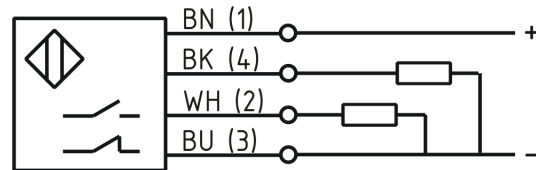

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Operating state

Switching state

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Throughbeam sensor

10 - 30 V DC

150 mA

< 30 mA

150

-25 ° C to 70 ° C

LED

LED

60 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

2m PVC 4x0,5mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363255026](#)