

[Article Page](#)

Product Description

Name

Order number

Illuminant

Connection

one-way light barrier


KOES60M-M30MB96-D-V2-IR

08363255036

IR Infrared light 880 nm

 Connector

Connection diagramm

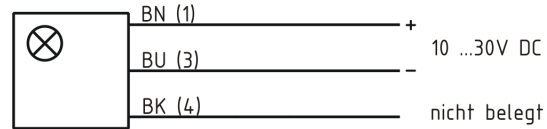

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Operating temperature

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Throughbeam sensor

10 - 30 V DC

150 mA

< 30 mA

-25 ° C to 70 ° C

60 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363255036](#)