

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

fibre optic device

KOLL-Q30KB-DPA-V1-RT

08365821064

9882-1064




Changeover

DC PNP

● Red light 660 nm



Connector

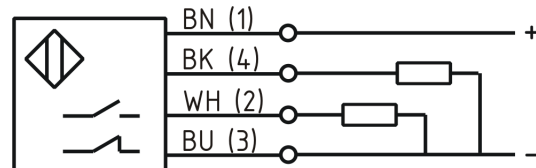

15 x 30 x 30

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Switching state

Digital output

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Housing material

Termination

Notes

Fibre-optic sensor

10 - 36 V DC

200 mA

< 15 mA

1000

-25 ° C to 55 ° C

LED

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Plastic

Connector M8 4pol

max. Laststrom 200mA

(bei antivalent Summe beider Ausgänge)

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08365821064](#)