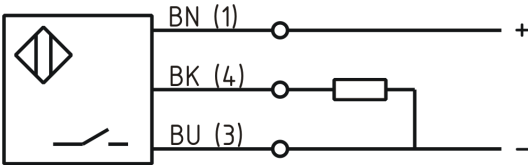


[Article Page](#)

Product Description		background suppression sensor	
Name	KORH150-Q30KB-DPS-V1-RT		
Order number	08361822164		
Matchcode	9982-2164		
Switch type	 N.O.		
Signal Type	DC PNP		
Illuminant	 Red light 660 nm		
Connection	 Connector		
Connection diagramm			
Dimension (in mm)	15 x 30 x 30		
Technical Specification			
Signal type	Background suppression sensor		
Operating voltage	10 - 36 V DC		
Max. load current	200 mA		
No load current	< 15 mA		
Switching frequency	500		
Operating temperature	-25 ° C to 55 ° C		
Switching state	LED		
Digital output			
Sensitivity adjustable	nein		
Sensing range adjustable	ja		
Working range	from 15 to 150 mm		
Short-circuit proof	yes		
Overload protection	yes		
Reverse voltage protection	yes		
Protection category	IP65		
EMC-level	DIN EN 60947-5-2:2008		
Housing material	Plastic		
Termination	Connector M8 3pol		

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361822164](#)