

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switching distance

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

reflex light probe with background suppression

KORH400-M30MB96-DPA-V2-IR

08361255057

M30B-D0400P-CX9Q4UE-BS

400 mm




Changeover

DC PNP

IR Infrared light 880 nm



Connector

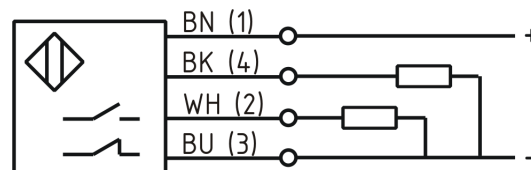

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Operating state

Switching state

Digital output

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Background suppression sensor

10 - 30 V DC

150 mA

< 30 mA

150

-25 ° C to 70 ° C

LED

LED

nein

ja

yes

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361255057](#)