

[Article Page](#)

Product Description

Name

polarized reflex light barrier  
KORP1000-M18MB85-DPU-V2-RT

Order number


08362250257

Matchcode

M18B-L1000P-CX6Q4UE-PF

Switch type

100110

 Programmable

Signal Type

DC PNP


Illuminant

 Red light 650 nm

Connection

 Connector

Connection diagramm

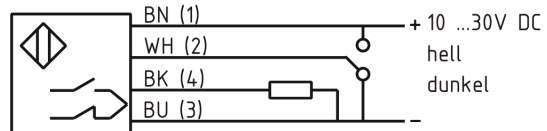

Technical Specification

Signal type

Polarized retroreflective sensor

Operating voltage

10 - 30 V DC

Max. load current

200 mA

No load current

< 30 mA

Switching frequency

300

Operating temperature

-25 ° C to 55 ° C

Switching state

LED

Digital output

Measuring range

1 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Termination

Connector M12 4pol

**Errors and omissions excepted**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362250257](#)