
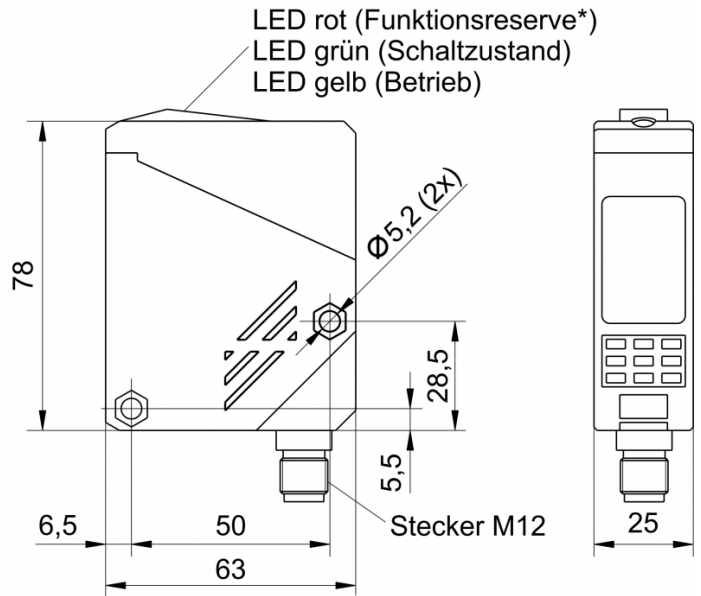


[Article Page](#)

Product Description

reflex light barrier

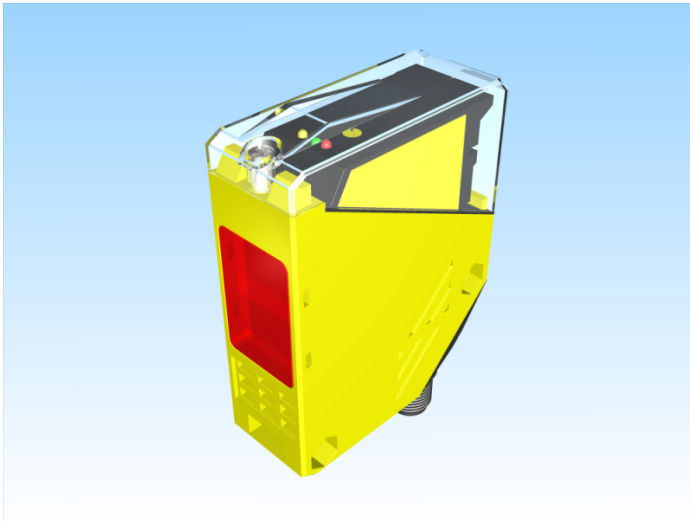

Name

KORP10M-Q76KB-DPU-V2-RT

Order number

08362280026

Switch type

Switchable

Signal Type


PNP

Illuminant

Red light 660 nm
connector M12

Connection

Connection diagramm

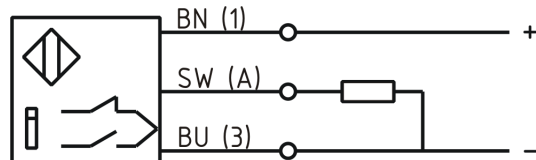

Q 25 x 77.5 x 63

Dimension (in mm)

Technical Specification

Signal type

Polarized retroreflective sensor

Operating voltage

10 - 30 V DC

Max. load current

100 mA

No load current

< 35 mA

Switching frequency

500 Hz

Operating temperature

-25 ° C to 55 ° C

Operating state

LED

Switching state

LED

Measuring range

10 m

Sensitivity adjustable

ja

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Housing material

Plastic

Termination

Connector M12 4pol (pivotable: 0° oder 90°)

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362280026](#)