
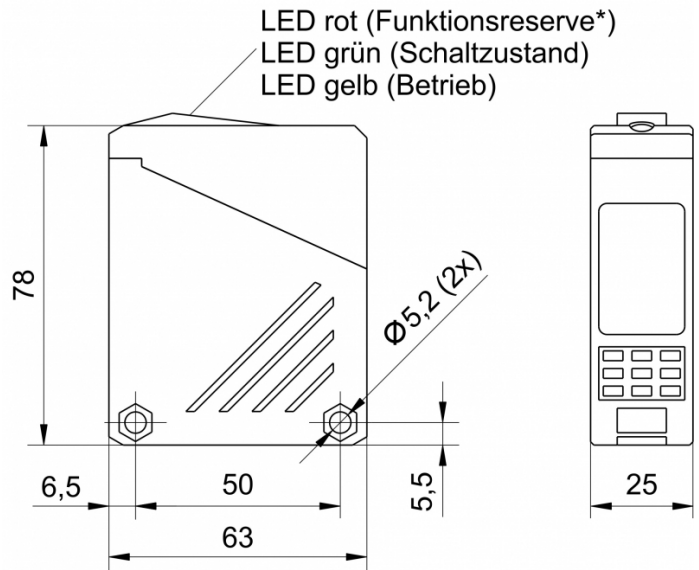


[Article Page](#)

Product Description

reflex light barrier

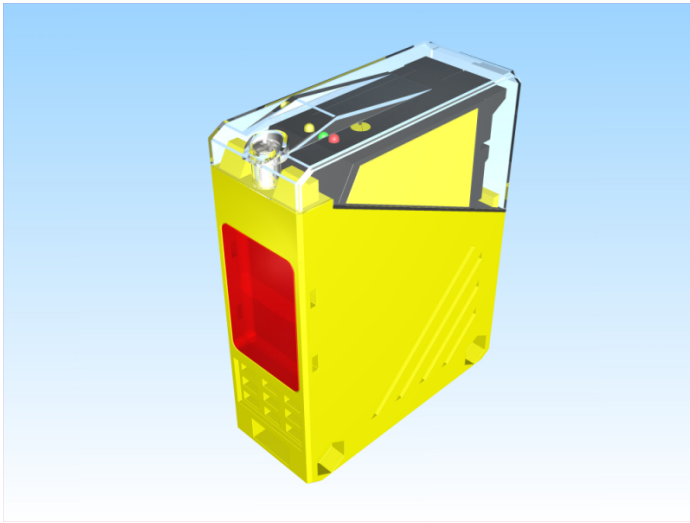

Name

Order number

Switch type

KORP10M-Q76KB-VRU-NPT-RT

08362280007



Switchable

Relay

Red light 660 nm


Terminal

Signal Type

Illuminant

Connection

Connection diagramm

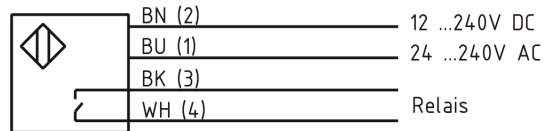

Q 25 x 77.5 x 63

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Operating state

Switching state

Measuring range

Sensitivity adjustable

Reverse voltage protection

Protection category

EMC-level

Housing material

Polarized retroreflective sensor

12 - 240 V DC / 24,00 - 240,00 V AC

3000 mA

< 30 mA

25 Hz

-25 ° C to 55 ° C

LED

LED

10 m

ja

yes

IP65

DIN EN 60947-5-2:2008

Plastic

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362280007](#)