

[Article Page](#)

Product Description

Name

polarized reflex light barrier

Order number

KORP13M-Q64KB-DPU-RT

Matchcode

08362215001

Switch type

RP64-L013MP-CY6C4U2-PF

100110

↓ Programmable

Signal Type

DC NPN


Illuminant

● Red light 650 nm

Connection

— Cable

Connection diagramm

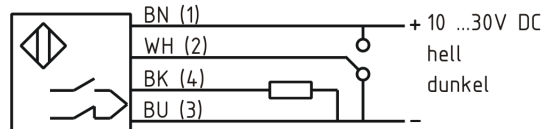

Q 20 x 60 x 43

Dimension (in mm)

Technical Specification

Polarized retroreflective sensor

Signal type

10 - 30 V DC

Operating voltage

Max. load current

100 mA

No load current

< 35 mA

Switching frequency

700

Operating temperature

-25 ° C to 55 ° C

Switching state

LED

Measuring range

13 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Housing material

Plastic

Termination

2m PVC 4x0,5mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362215001](#)