

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

polarized reflex light barrier
KORP2000-Q31KB-DMU-V1-RT
08362260021
MP-L2000D-CX6Q4UP-PF




Switchable

DC PNP/NPN

● Red light 650 nm



Connector

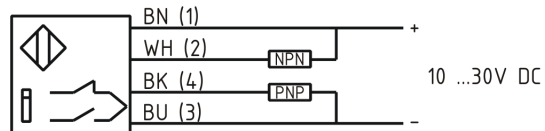

12 x 31 x 30

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Switching state

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Housing material

Termination

Polarized retroreflective sensor

10 - 30 V DC

150 mA

< 25 mA

500

-25 ° C to 70 ° C

LED

2 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Plastic

Connector M8 4pol

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362260021](#)