

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

polarized reflex light barrier
 KORP6000-M30MB78-DPA-RT
 08362255017
 M30B-L6000P-CX6C4U2-PF




Changeover

DC PNP

● Red light 650 nm



Cable

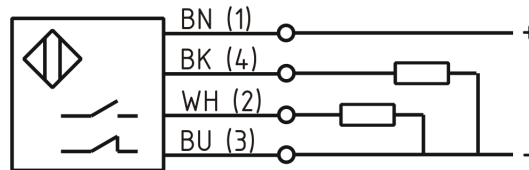

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Operating state

Switching state

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Polarized retroreflective sensor

10 - 30 V DC

150 mA

< 30 mA

150

-25 ° C to 70 ° C

LED

LED

6 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

2m PVC 4x0,5mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362255017](#)