

[Article Page](#)

Product Description

Name
Order number
Matchcode
Switch type

polarized reflex light barrier
KORP6000-M30MB96-DPA-V2-RT
08362255025
M30B-L6000P-CX6Q4UE-PF


 Changeover
DC PNP

 Red light 650 nm

 Connector

Signal Type
Illuminant
Connection

Connection diagramm

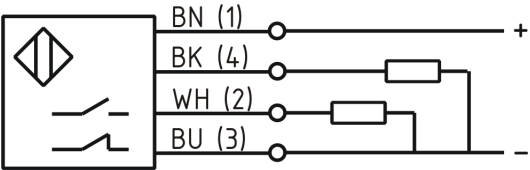

Technical Specification

Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Operating state
Switching state
Digital output
Measuring range
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Termination

Polarized retroreflective sensor
10 - 30 V DC
150 mA
< 30 mA
150
-25 ° C to 70 ° C
LED
LED

6 m
ja
nein
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362255025](#)