

[Article Page](#)

Product Description

Name
Order number
Matchcode
Switch type

reflex light barrier
KORS2000-Q30KB-DPS-V1-RT
08361822264
9882-2264


Signal Type
Illuminant
Connection

 N.O.
DC PNP
 Red light 660 nm

Connection diagramm

 Connector

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Switching state
Digital output
Measuring range
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

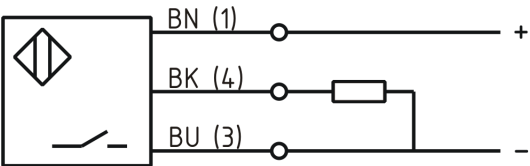

15 x 30 x 30

Polarized retroreflective sensor
10 - 36 V DC
200 mA
< 15 mA
1000
-25 ° C to 55 ° C
LED

2 m
ja
nein
yes
yes
yes
IP65
DIN EN 60947-5-2:2008
Plastic
Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361822264](#)