

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

reflex light barrier

KORS4000-Q30KB-DPA-V1-RT

08362820464

9882-0464




Changeover

DC PNP

● Red light 660 nm



Connector

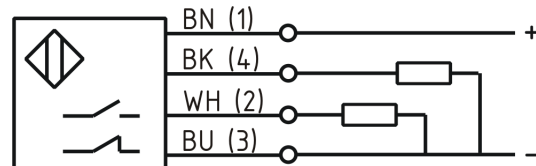

15 x 30 x 30

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Switching state

Digital output

Measuring range

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Housing material

Termination

Notes

Retroreflective sensor

10 - 36 V DC

200 mA

< 15 mA

1000

-25 ° C to 55 ° C

LED

4 m

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Plastic

Connector M8 4pol

Max. Laststrom 200mA

(bei antivalent Summe beider Ausgänge)

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08362820464](#)