

[Article Page](#)

Product Description

Name
Order number
Matchcode
Switching distance
Switch type

 
reflex light probe
KORT130-Q31KB-DMU-IR
08361260017
MP-D0130D-CX9C4U2
130 mm



Switchable


Signal Type
Illuminant
Connection

DC PNP/NPN
IR Infrared light 880 nm



Cable

Connection diagramm

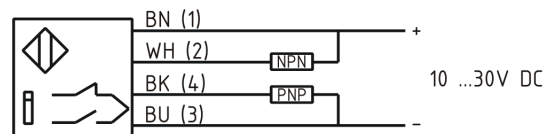

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Switching state
Digital output
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

12 x 31 x 30
Diffuse mode sensor
10 - 30 V DC
150 mA
< 25 mA
500
-25 ° C to 70 ° C
LED
ja
nein
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Plastic
2m PVC 4x0,5mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361260017](#)