
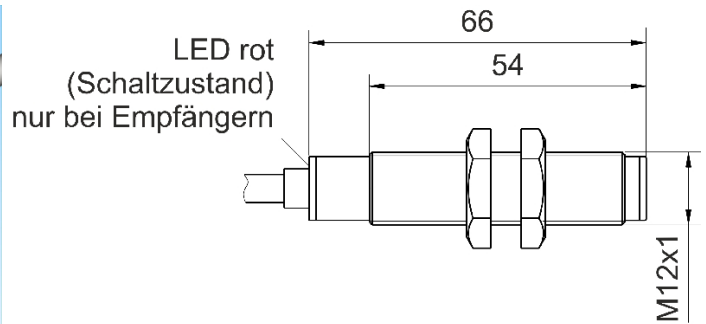


[Article Page](#)

Product Description

reflex light probe

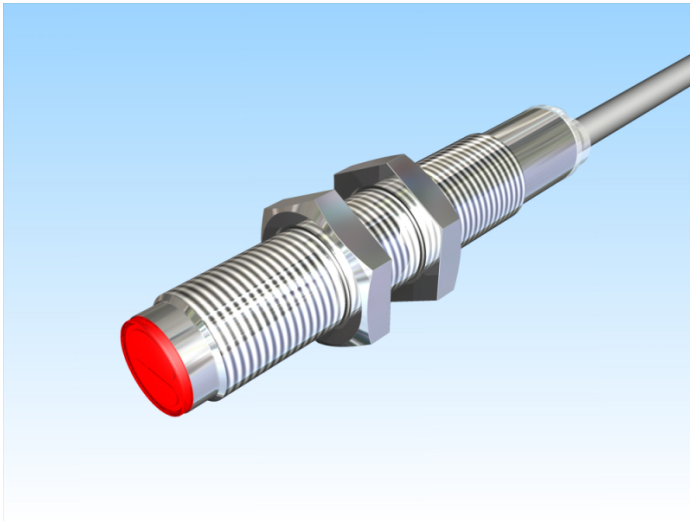

Name

KORT200-M12MB64-DPA-IR

Order number

08361245123

Switching distance

200 mm

Switch type



Changeover

Signal Type

PNP

Illuminant


IR Infrared light 880 nm

Connection



Cable

Connection diagramm

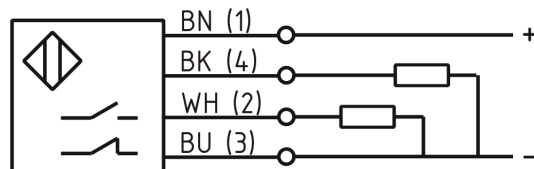

M12 x 64

Dimension (in mm)

Technical Specification

Signal type

Diffuse mode sensor

Operating voltage

10 - 30 V DC

Max. load current

150 mA

No load current

< 30 mA

Switching frequency

500 Hz

Operating temperature

-25 ° C to 70 ° C

Switching state

LED

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Termination

2m PVC 4x0,14mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361245123](#)